


Speed Sensor (Inductive)

94301 00013 / 94301 00110




Dimensions

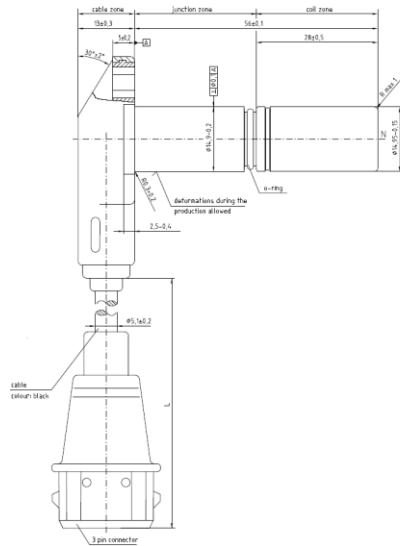


Resistance	920 Ω ± 10 %	Inductivity	810 mH ± 15 %	Signal sequence	On connection 1(+) 1. half wave positive
Temperature range	-40 °C to 110 °C	Mounting hole	15 H7	Shaft length	56 ± 0.1 mm
Connector	3-pin Mini-Timer, female connector on request	Cable length "L"	380 ± 15 mm (..00013) 610 ± 15 mm (..00110)		

Connector

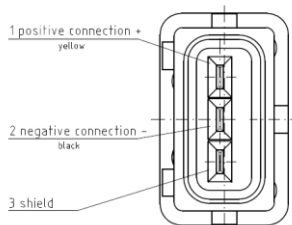

Output signal

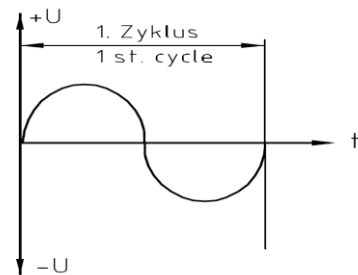

Technical status acc. to specification 29.11.1994